

Technical data sheet

90° bend 60 FT

Item number: 6225059



90° bend, horizontal, with welded rung for all cable ladder types of 60 mm side height.
Connectors should be ordered separately and in the appropriate quantity.



St	Steel
FT	Hot-dip galvanised

Master data

Item number	6225059
Type	LB 90 610 R3 FT
Description 1	90° bend
Description 2	for cable ladder
Manufacturer	OBO
Dimension	60x100
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	211 kg
Weight unit	kg/100 pc.


Technical data sheet

90° bend 60 FT

Item number: 6225059



Dimensions

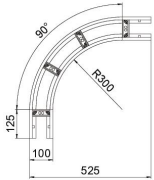

Height	60 mm
--------	-------

Technical data

Bend (angle)	90°
Version of the rungs	Profile perforated
Side rail version	Flat profile
Connector version	Without connectors
Maintain electrical functions	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Hinged	no
Side perforation	no
Wide-span version	no
Rail thickness	1.5 mm