

Technical data sheet

90° bend 60 FS

Item number: 6211426



Horizontal 90° bend, fitting for cable ladders, side height 60 mm With connector perforation. Can be used in indoor areas. Connector and fastening material must be ordered separately. Fittings must be supported by the support structure.



St	Steel
FS	Strip galvanized

Master data

Item number	6211426
Type	LB 90 640 R5 FS
Description 1	90° bend
Description 2	for cable ladder, horizontal
Manufacturer	OBO
Dimension	60x400
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	470 kg
Weight unit	kg/100 pc.


Technical data sheet

90° bend 60 FS

Item number: 6211426



Dimensions

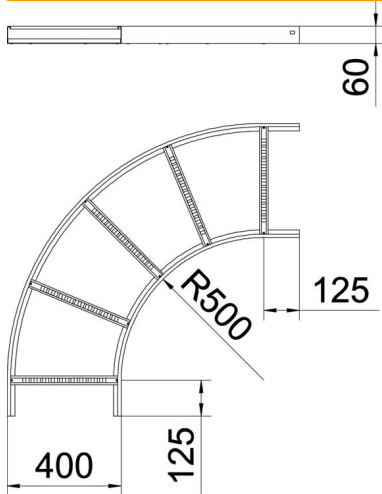

Width	400 mm
Height	60 mm
Dimension B	400 mm
Dimension R	400 mm

Technical data

Bend (angle)	90°
Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Change of direction	Horizontal
Rustproof steel, pickled	no
Hinged	no
Side perforation	no
Wide-span version	no
Rail thickness	1.5 mm