

# Technical data sheet

90° bend 60 FT

Item number: 6211456



Horizontal 90° bend, fitting for cable ladders, side height 60 mm With connector perforation. Can be used indoors and outdoors. Connector and fastening material must be ordered separately. Fittings must be supported by the support structure.



|    |                    |
|----|--------------------|
| St | Steel              |
| FT | Hot-dip galvanised |

## Master data

|                     |                              |
|---------------------|------------------------------|
| Item number         | 6211456                      |
| Type                | LB 90 650 R5 FT              |
| Description 1       | 90° bend                     |
| Description 2       | for cable ladder, horizontal |
| Manufacturer        | OBO                          |
| Dimension           | 60x500                       |
| Colour              | zinc                         |
| Material            | Steel                        |
| Surface             | Hot-dip galvanised           |
| Surface standard    | DIN EN ISO 1461              |
| Smallest sales unit | 1                            |
| Unit of quantity    | Piece                        |
| Weight              | 602 kg                       |
| Weight unit         | kg/100 pc.                   |


# Technical data sheet

90° bend 60 FT

Item number: 6211456



## Dimensions

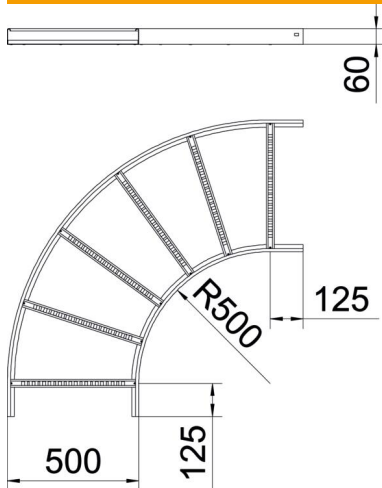

|             |        |
|-------------|--------|
| Width       | 500 mm |
| Height      | 60 mm  |
| Dimension B | 500 mm |
| Dimension R | 500 mm |

## Technical data

|                               |                      |
|-------------------------------|----------------------|
| Bend (angle)                  | 90°                  |
| Version of the rungs          | Profile unperforated |
| Side rail version             | Flat profile         |
| Connector version             | Without connectors   |
| Maintain electrical functions | no                   |
| Change of direction           | Horizontal           |
| Rustproof steel, pickled      | no                   |
| Hinged                        | no                   |
| Side perforation              | no                   |
| Wide-span version             | no                   |
| Rail thickness                | 1.5 mm               |