

Technical data sheet

Cover for articulated bend element FT

Item number: 6226252



Cover with sash locks for covering adjustable bends with welded rungs.



St	Steel
FT	Hot-dip galvanised

Master data

Item number	6226252
Type	LGBED 1200 FT
Description 1	Cover for articulated bend
Description 2	vertical, with turn buckle
Manufacturer	OBO
Dimension	B1200
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	290 kg
Weight unit	kg/100 pc.


Technical data sheet

Cover for articulated bend element FT

Item number: 6226252



Dimensions

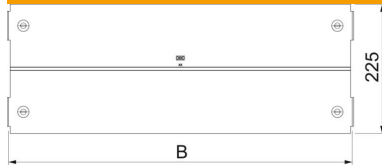

Width	1,200 mm
Plate thickness	1.25 mm
Dimension B	1,200 mm

Technical data

Bend (angle)	Adjustable
Fastening type	Sash lock
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	yes
Suitable for cable tray	no
Change of direction	Vertical, rising/falling
Rustproof steel, pickled	no
Hinged	no