

Technical data sheet

90° adjustable bend, vertical 110 FT

Item number: 6218954



90° adjustable vertical bend, for all cable ladder types with a side height of 110 mm.
The fitting is shipped in an unmounted state including adjustable connectors and the appropriate bolts.



- St

Steel
- FT

Hot-dip galvanised

Master data

Item number	6218954
Description 1	Adjustable bend
Description 2	vertical, with VS rung
Manufacturer	OBO
Dimension	110x400
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	488 kg
Weight unit	kg/100 pc.


Technical data sheet

90° adjustable bend, vertical 110 FT

Item number: 6218954



Dimensions

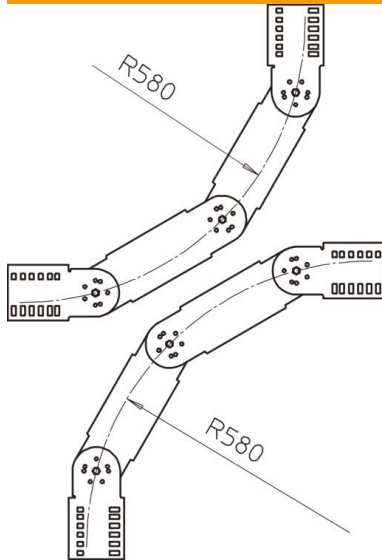

Width	400 mm
Height	110 mm

Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Rustproof steel, pickled	no
Hinged	yes
Side perforation	no
Wide-span version	no
Rail thickness	1.5 mm