

# Technical data sheet

## Adjustable bend, vertical, VS 60 FT

Item number: 6213332



90° adjustable vertical bend, for cable ladders with medium-duty rung (VS) and a side height of 60 mm.  
The fitting is shipped in an unmounted state including adjustable connectors and the appropriate bolts.  
Additional widths are available on request.



St	Steel
FT	Hot-dip galvanised

### Master data

Item number	6213332
Description 1	Adjustable bend
Description 2	vertical, with VS rung
Manufacturer	OBO
Dimension	60x300
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	301 kg
Weight unit	kg/100 pc.


# Technical data sheet

Adjustable bend, vertical, VS 60 FT

Item number: 6213332



## Dimensions

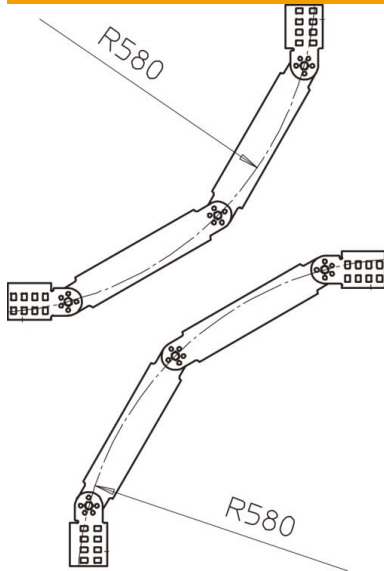

Width	300 mm
Height	60 mm

## Technical data

Bend (angle)	90°
Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Rustproof steel, pickled	no
Hinged	yes
Side perforation	no
Wide-span version	no
Rail thickness	1.5 mm