

Technical data sheet

Adjustable bend, vertical, VS 60 FS

Item number: 6213278



90° adjustable vertical bend, for cable ladders with medium-duty rung (VS) and a side height of 60 mm.
The fitting is shipped in an unmounted state including adjustable connectors and the appropriate bolts.
Additional widths are available on request.



St	Steel
FS	Strip galvanized

Master data

Item number	6213278
Type	LGBV 660 VS FS
Description 1	Adjustable bend
Description 2	vertical, with VS rung
Manufacturer	OBO
Dimension	60x600
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	374 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	10,6338 kg CO2e / 1 Piece


Technical data sheet

Adjustable bend, vertical, VS 60 FS

Item number: 6213278



Dimensions

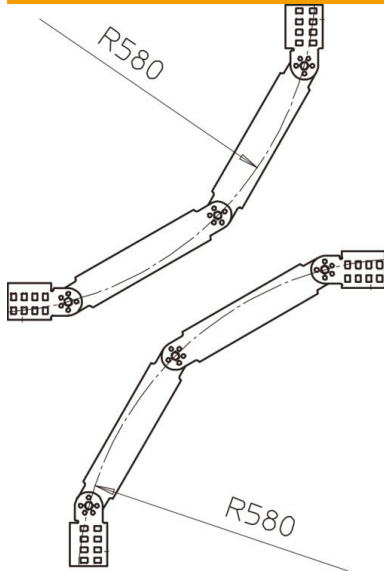

Width	600 mm
Height	60 mm

Technical data

Bend (angle)	90°
Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Rustproof steel, pickled	no
Hinged	yes
Side perforation	no
Wide-span version	no
Rail thickness	1.5 mm