

Technical data sheet


Adjustable connector FT

Item number: 6216653



Adjustable connector as internal connector to join cable ladders and fittings with a side height of 110 mm. Angle can be adjusted vertically.

The bolt fastening ensures the continuity of the equipotential bonding.

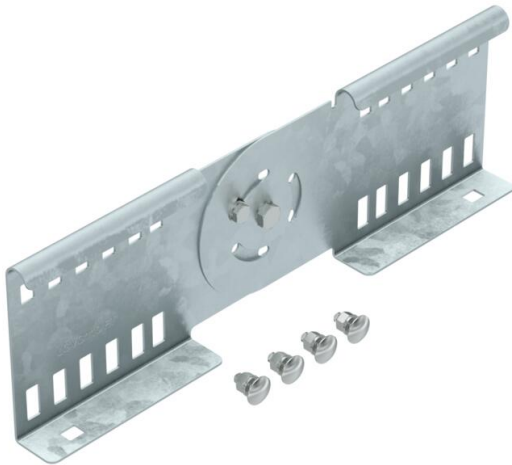

St	Steel
FT	Hot-dip galvanised

Master data

Item number	6216653
Description 1	Adjustable connector
Description 2	for cable ladder
Manufacturer	OBO
Dimension	114x360
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	10
Unit of quantity	Piece
Weight	82.1 kg
Weight unit	kg/100 pc.

 
Technical data sheet

Adjustable connector FT

Item number: 6216653



Dimensions



Dimension	314x360
Length	360 mm
Width	28 mm
Height	110 mm
Plate thickness	1.5 mm

Technical data

Version for	Straight and angle connector
Suitable for mesh cable tray	no
Suitable for cable ladder	yes
Suitable for cable tray	no
Suitable for cable tray system height	110 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	yes
Rustproof steel, pickled	no
Connection type	Screw connector