


Technical data sheet

Cover LK4H 40

Item number: 6132585



Trunking cover for replacement requirements.

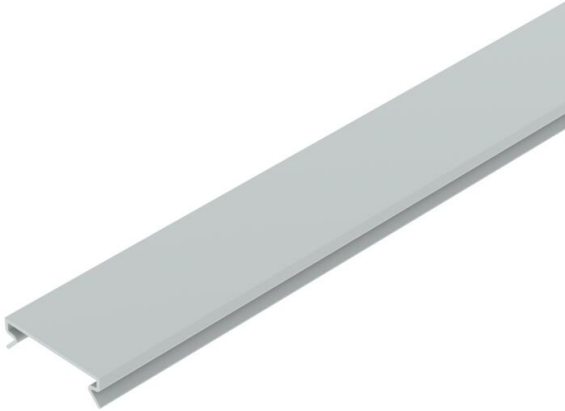


Polycarbonate/Acrylnitrile-butadiene-styrene

Master data

Item number	6132585
Type	LK4H D 40
Description 1	Cover
Description 2	for LK4H
Manufacturer	OBO
Dimension	2000x40x10
Colour	Light grey; RAL 7035
Material	Polycarbonate/Acrylnitrile-butadiene-styrene
Smallest sales unit	2
Unit of quantity	Metre
Weight	13 kg
Weight unit	kg/100 m

Dimensions

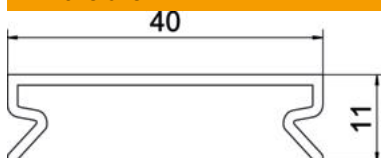

Length	2,000 mm
Width	40 mm
Height	10 mm

Technical data sheet

Cover LK4H 40

Item number: 6132585



Technical data

for duct width	40 mm
Halogen-free	yes
Creepage current-resistant	yes
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-25 °C