

Technical data sheet

Cable duct, type LKM 40060

Item number: 6247016



Duct cover and base with base perforation.

Equipotential bonding is guaranteed between the cover and the base without any additional aids.



St	Steel
FS	Strip galvanized

Master data

Item number	6247016
Type	LKM40060FS
Description 1	Cable trunking
Description 2	with base perforation
Manufacturer	OBO
Dimension	40x60x2000
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	2
Unit of quantity	Metre
Weight	151.2 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	3,5985 kg COe / 1 Meter


Technical data sheet

Cable duct, type LKM 40060

Item number: 6247016



Dimensions

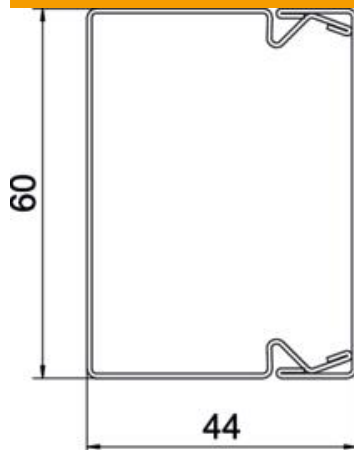

Length	2,000 mm
Width	60 mm
Height	44 mm

Technical data

Number of fixed partitions	0
Number of cables NYM 3 x 1.5 mm ² Ø 10.5 mm (without socket)	10
Number of cables NYM 3 x 2.5 mm ² Ø 11.5 mm (without socket)	10
Number of cables NYM 5 x 1.5 mm ² Ø 12.0 mm (without socket)	8
Number of insertable partitions	0
Version, cable trunking cover	Loose
Fastening type	Base perforation
Base perforation	with base perforation
Maintain electrical functions	no
Halogen-free	yes
Cable retaining clip	no
Duct connector	no
Delivery on a roll	no
Usable cross-section	2380 mm ²
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C
Transparent	no