

Technical data sheet

Flat angle, for cable trunking type LKM 40040

Item number: 6247490



Flat angle including cover for changing the direction of the LKM ducts.
Equipotential bonding without additional aids, between base and cover



St	Steel
FS	Strip galvanized

Master data

Item number	6247490
Type	LKM F40040FS
Description 1	Flat angle
Description 2	with cover
Manufacturer	OBO
Dimension	40x40mm
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	37.1 kg
Weight unit	kg/100 pc.


Technical data sheet

Flat angle, for cable trunking type LKM 40040

Item number: 6247490



Dimensions

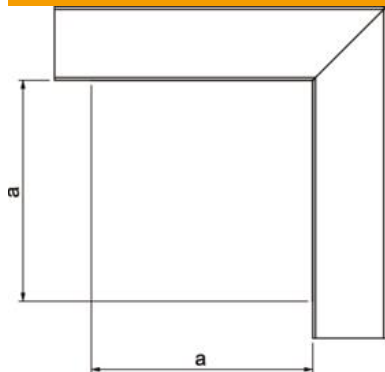

Length	180 mm
Width	40 mm
Height	44 mm
Dimension a	140 mm

Technical data

Version for	Base and cover
Fastening type	Base perforation
Maintain electrical functions	no
for duct dimension	40 x 40
Halogen-free	yes
Duct height, min.	44 mm
Trunking depth	44 mm
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Self-extinguishing	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm