

# Technical data sheet

Flat angle, for cable duct type LKM 60100

Item number: 6249507



Flat angle including cover for changing the direction of the LKM ducts.  
Equipotential bonding without additional aids, between base and cover



Steel



Strip galvanized / plastic coated

## Master data

|                     |                                   |
|---------------------|-----------------------------------|
| Item number         | 6249507                           |
| Type                | LKM F60100RW                      |
| Description 1       | Flat angle                        |
| Description 2       | with cover                        |
| Manufacturer        | OBO                               |
| Dimension           | 60x100mm                          |
| Colour              | Pure white; RAL 9010              |
| Material            | Steel                             |
| Surface             | Strip galvanized / plastic coated |
| Surface standard    | DIN EN 10346                      |
| Smallest sales unit | 1                                 |
| Unit of quantity    | Piece                             |
| Weight              | 63.4 kg                           |
| Weight unit         | kg/100 pc.                        |


# Technical data sheet

Flat angle, for cable duct type LKM 60100

Item number: 6249507



## Dimensions

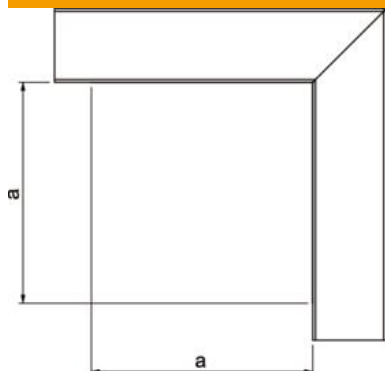

|             |        |
|-------------|--------|
| Length      | 240 mm |
| Width       | 100 mm |
| Height      | 64 mm  |
| Dimension a | 140 mm |

## Technical data

|                                   |                  |
|-----------------------------------|------------------|
| Version for                       | Base and cover   |
| Fastening type                    | Base perforation |
| Maintain electrical functions     | yes              |
| for duct dimension                | 60 x 100         |
| Halogen-free                      | yes              |
| Duct height, min.                 | 64 mm            |
| Trunking depth                    | 64 mm            |
| Protection rating                 | IP30             |
| Protective film                   | no               |
| Protection rating IK code         | IK10             |
| Self-extinguishing                | no               |
| Permitted temperature range, max. | 90 °C            |
| Permitted temperature range, min. | -5 °C            |
| Angle range, max.                 | 90 mm            |
| Angle range, min.                 | 90 mm            |