

Technical data sheet

Internal corner, for cable trunking type LKM 80080

Item number: 6248336



Internal corner for changing the direction of LKM trunking.
Equipotential bonding without additional aids, between base and cover



St	Steel
FS	Strip galvanized

Master data

Item number	6248336
Type	LKM I80080FS
Description 1	Internal corner
Manufacturer	OBO
Dimension	80x80mm
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	38.7 kg
Weight unit	kg/100 pc.

Technical data sheet


Internal corner, for cable trunking type LKM 80080

Item number: 6248336



Dimensions

Length	160 mm
Width	80 mm
Height	80 mm
Dimension a	160 mm

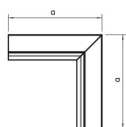

Technical data

Version for	Base
Fastening type	Base perforation
Maintain electrical functions	no
Halogen-free	yes
Protection rating	IP30
Protective film	no
Protection rating IK code	IK10
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C
Angle range, max.	90 mm
Angle range, min.	90 mm