


Technical data sheet

Trunking clamp, LKM, trunking width 80 mm

Item number: 6249882

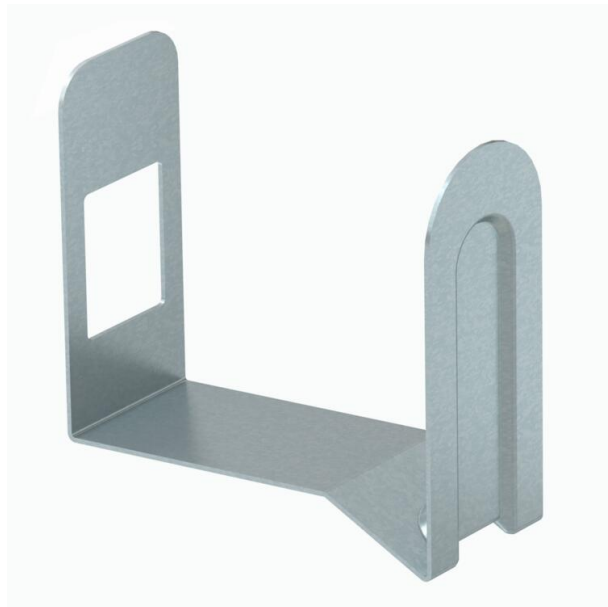

The trunking clamp keeps the inserted cables in the trunking, thus simplifying installation on walls and ceilings. The trunking clamps are plugged onto the loop perforation and locked on the side wall. Suitable for trunking width 80 mm.



St	Steel
GBP	galvanised, blue passivated

Master data

Item number	6249882
Type	LKM K65
Description 1	Trunking clamp
Manufacturer	OBO
Dimension	65mm
Colour	zinc
Material	Steel
Surface	galvanised, blue passivated
Surface standard	
Smallest sales unit	20
Unit of quantity	Piece
Weight	2.33 kg
Weight unit	kg/100 pc.


Technical data sheet

Trunking clamp, LKM, trunking width 80 mm

Item number: 6249882



Dimensions

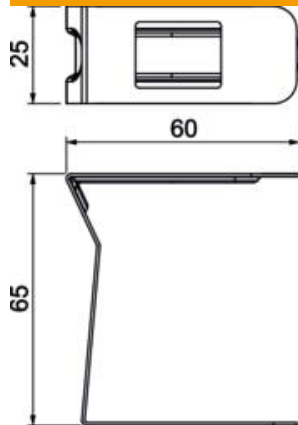

Length	25 mm
Width	60 mm
Height	65 mm
Dimension a	25 mm
Dimension b	60 mm
Dimension c	65 mm

Technical data

Fastening type	Lockable
Maintain electrical functions	no
for duct dimension	80 x 80
Halogen-free	yes
With equipotential bonding	no
Cover width	80 mm
Protection rating	IP30
Protection rating IK code	IK10
Self-extinguishing	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C