

Technical data sheet

Partition LKM TWS75

Item number: 6249880



Partition to divide the LKM cable routing trunking, 80 mm trunking height, for different voltage levels.

The loop perforation in the base transfers the equipotential bonding to the partition.



St	Steel
FS	Strip galvanized

Master data

Item number	6249880
Type	LKM TWS75
Description 1	Partition
Manufacturer	OBO
Dimension	75x2000mm
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	2
Unit of quantity	Metre
Weight	57 kg
Weight unit	kg/100 m


Technical data sheet

Partition LKM TWS75

Item number: 6249880



Dimensions

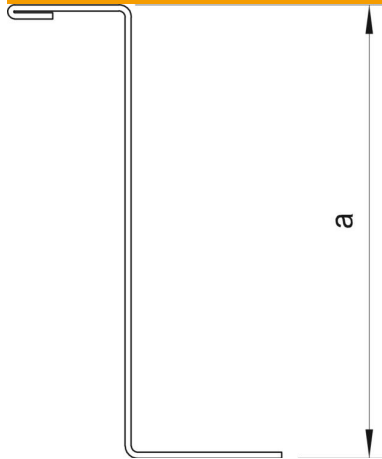

Length	2,000 mm
Width	33 mm
Height	60 mm
Dimension a	60 mm

Technical data

Version for	Single
Fastening type	Plug-in
Halogen-free	yes
Trunking depth	80 mm
Protection rating	IP30
Protection rating IK code	IK10
Self-extinguishing	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C