


Technical data sheet

LKM cable bracket, duct width 100 mm

Item number: 6249922



Cable bracket to fix cables in vertical routing.

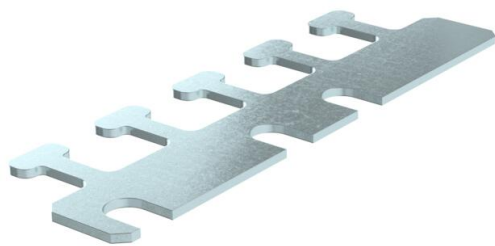

- St** Steel
- FS** Strip galvanized

Master data	
Item number	6249922
Type	LKM Z100
Description 1	Cable fixing device
Manufacturer	OBO
Dimension	100mm
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	10
Unit of quantity	Piece
Weight	2.1 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1174 kg CO2e / 1 Piece


Technical data sheet

LKM cable bracket, duct width 100 mm

Item number: 6249922



Dimensions

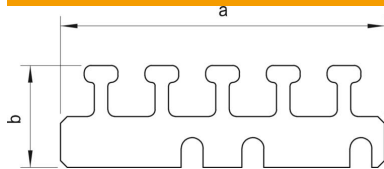

Length	30 mm
Width	96 mm
Height	1.4 mm
Dimension a	96 mm
Dimension b	30 mm

Technical data

Fastening type	Screw-on
Maintain electrical functions	yes
for duct dimension	60 x 100 mm
Halogen-free	yes
With equipotential bonding	no
Cover width	100 mm
Protection rating	IP30
Protection rating IK code	IK10
Self-extinguishing	no
Permitted temperature range, max.	90 °C
Permitted temperature range, min.	-5 °C