


Technical data sheet

Cross-over 60 FT

Item number: 6214458



Cross-over for the creation of horizontal branches, fitting for cable ladders of side height 60 mm. With connector perforation. Can be used indoors and outdoors. Connector and fastening material must be ordered separately. Fittings must be supported by the support structure.

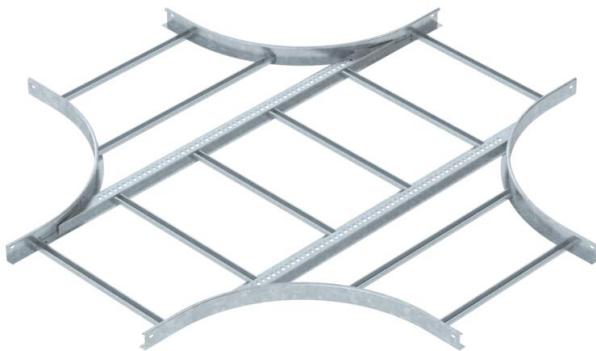

St	Steel
FT	Hot-dip galvanised

Master data

Item number	6214458
Type	LK 660 R5 FT
Description 1	Cross over
Description 2	for cable ladder, horizontal
Manufacturer	OBO
Dimension	60x600
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	1519 kg
Weight unit	kg/100 pc.


Technical data sheet

Cross-over 60 FT

Item number: 6214458



Dimensions

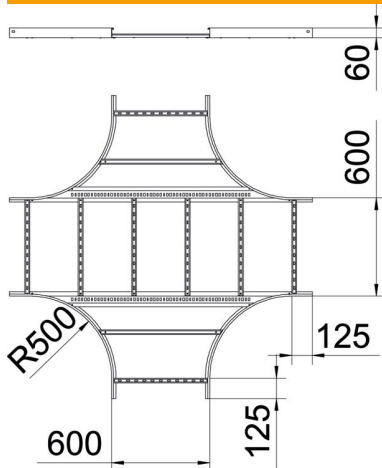

Width	600 mm
Height	60 mm
Dimension B	600 mm
Dimension R	500 mm

Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	no
Rail thickness	1.5 mm