

Technical data sheet

T piece 110 FS

Item number: 6219388



T piece to create a horizontal branch, fittings for cable ladders of side height 110 mm. With connector perforation. Can be used in indoor areas. Connector and fastening material must be ordered separately. Fittings must be supported by the support structure.



St	Steel
FS	Strip galvanized

Master data

Item number	6219388
Type	LT 1150 R5 FS
Description 1	T piece
Description 2	for cable ladder, horizontal
Manufacturer	OBO
Dimension	110x500
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	1054 kg
Weight unit	kg/100 pc.


Technical data sheet

T piece 110 FS

Item number: 6219388



Dimensions

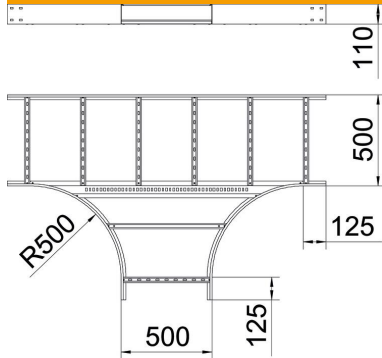

Width	500 mm
Height	110 mm
Dimension B	500 mm
Dimension R	500 mm

Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	no
Rail thickness	1.5 mm