

Technical data sheet

T piece 60 A2

Item number: 6225250



T piece, horizontal, with welded rung for all cable ladder types of 60 mm side height.
Connectors should be ordered separately and in the appropriate quantity.



- A2 Stainless steel
- 2B Bright, treated

Master data	
Item number	6225250
Description 1	T piece
Description 2	for cable ladder
Manufacturer	OBO
Dimension	60x200
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	474.6 kg
Weight unit	kg/100 pc.


Technical data sheet

T piece 60 A2

Item number: 6225250



Dimensions

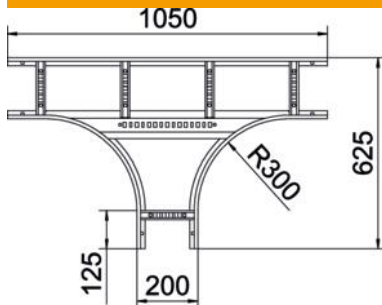

Width	200 mm
Height	60 mm
Dimension B	200 mm
Dimension R	300 mm

Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Connector version	Without connectors
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	no
Rail thickness	1.5 mm