

# Technical data sheet

## T piece 60 FS

Item number: 6225210



T piece, horizontal, with welded rung for all cable ladder types of 60 mm side height.  
Connectors should be ordered separately and in the appropriate quantity.



|    |                  |
|----|------------------|
| St | Steel            |
| FS | Strip galvanized |

### Master data

|                     |                  |
|---------------------|------------------|
| Item number         | 6225210          |
| Description 1       | T piece          |
| Description 2       | for cable ladder |
| Manufacturer        | OBO              |
| Dimension           | 60x200           |
| Colour              | zinc             |
| Material            | Steel            |
| Surface             | Strip galvanized |
| Surface standard    | DIN EN 10346     |
| Smallest sales unit | 1                |
| Unit of quantity    | Piece            |
| Weight              | 468.7 kg         |
| Weight unit         | kg/100 pc.       |


# Technical data sheet

## T piece 60 FS

Item number: 6225210



### Dimensions

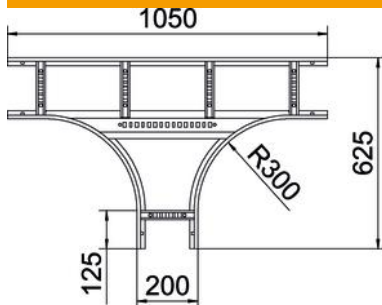

|             |        |
|-------------|--------|
| Width       | 200 mm |
| Height      | 60 mm  |
| Dimension B | 200 mm |
| Dimension R | 300 mm |

### Technical data

|                               |                      |
|-------------------------------|----------------------|
| Version of the rungs          | Profile unperforated |
| Side rail version             | Flat profile         |
| Connector version             | Without connectors   |
| Type                          | Exit symmetrical     |
| Maintain electrical functions | no                   |
| Rustproof steel, pickled      | no                   |
| Wide-span version             | no                   |
| Rail thickness                | 1.5 mm               |