

Technical data sheet

T piece 60 A2

Item number: 6225252



T piece, horizontal, with welded rung for all cable ladder types of 60 mm side height.
Connectors should be ordered separately and in the appropriate quantity.



A2 Stainless steel

2B Bright, treated

Master data

| | |
|---------------------|------------------|
| Item number | 6225252 |
| Description 1 | T piece |
| Description 2 | for cable ladder |
| Manufacturer | OBO |
| Dimension | 60x300 |
| Colour | stainless steel |
| Material | Stainless steel |
| Surface | Bright, treated |
| Surface standard | |
| Smallest sales unit | 1 |
| Unit of quantity | Piece |
| Weight | 537.8 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

T piece 60 A2

Item number: 6225252



Dimensions

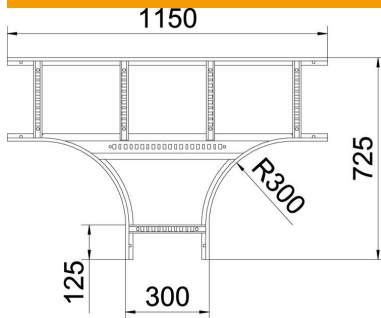

| | |
|-------------|--------|
| Width | 300 mm |
| Height | 60 mm |
| Dimension B | 300 mm |
| Dimension R | 300 mm |

Technical data

| | |
|-------------------------------|----------------------|
| Version of the rungs | Profile unperforated |
| Side rail version | Flat profile |
| Connector version | Without connectors |
| Type | Exit symmetrical |
| Maintain electrical functions | no |
| Rustproof steel, pickled | no |
| Wide-span version | no |
| Rail thickness | 1.5 mm |