


Technical data sheet

T piece 60 FT

Item number: 6225234



T piece, horizontal, with welded rung for all cable ladder types of 60 mm side height.
Connectors should be ordered separately and in the appropriate quantity.

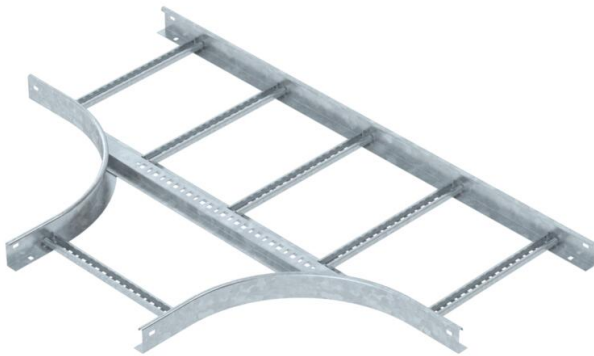

St	Steel
FT	Hot-dip galvanised

Master data

Item number	6225234
Description 1	T piece
Description 2	for cable ladder
Manufacturer	OBO
Dimension	60x400
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	656.5 kg
Weight unit	kg/100 pc.

Technical data sheet

T piece 60 FT

Item number: 6225234



Dimensions		
	Width	400 mm
	Height	60 mm
	Dimension B	400 mm
	Dimension R	300 mm

Technical data		
	Version of the rungs	Profile unperforated
	Side rail version	Flat profile
	Connector version	Without connectors
	Type	Exit symmetrical
	Maintain electrical functions	no
	Rustproof steel, pickled	no
	Wide-span version	no
	Rail thickness	1.5 mm