

# Technical data sheet

## T piece 60 A2

Item number: 6225256



T piece, horizontal, with welded rung for all cable ladder types of 60 mm side height.  
Connectors should be ordered separately and in the appropriate quantity.



**A2** Stainless steel

**2B** Bright, treated

### Master data

Item number	6225256
Description 1	T piece
Description 2	for cable ladder
Manufacturer	OBO
Dimension	60x500
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	697.4 kg
Weight unit	kg/100 pc.


# Technical data sheet

## T piece 60 A2

Item number: 6225256



### Dimensions

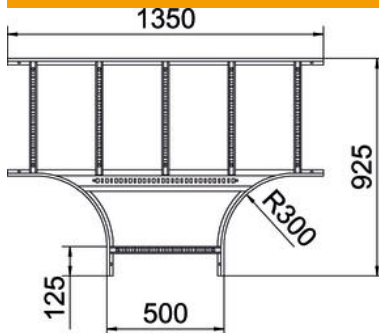

Width	500 mm
Height	60 mm
Dimension B	500 mm
Dimension R	300 mm

### Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Connector version	Without connectors
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	no
Rail thickness	1.5 mm