

Technical data sheet

T piece 60 A4

Item number: 6225276



T piece, horizontal, with welded rung for all cable ladder types of 60 mm side height.
Connectors should be ordered separately and in the appropriate quantity.



A4 Stainless steel

2B Bright, treated

Master data

Item number	6225276
Description 1	T piece
Description 2	for cable ladder
Manufacturer	OBO
Dimension	60x500
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	706.2 kg
Weight unit	kg/100 pc.


Technical data sheet

T piece 60 A4

Item number: 6225276



Dimensions

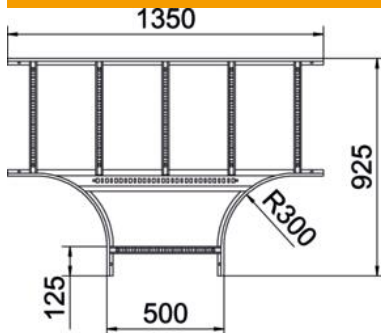

Width	500 mm
Height	60 mm
Dimension B	500 mm
Dimension R	300 mm

Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Connector version	Without connectors
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	no
Rail thickness	1.5 mm