

Technical data sheet

T piece 60 FS

Item number: 6225216



T piece, horizontal, with welded rung for all cable ladder types of 60 mm side height.
Connectors should be ordered separately and in the appropriate quantity.



St	Steel
FS	Strip galvanized

Master data

Item number	6225216
Type	LT 650 R3 FS
Description 1	T piece
Description 2	for cable ladder
Manufacturer	OBO
Dimension	60x500
Colour	zinc
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	688.6 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	20,1371 kg COe / 1 Piece


Technical data sheet

T piece 60 FS

Item number: 6225216



Dimensions

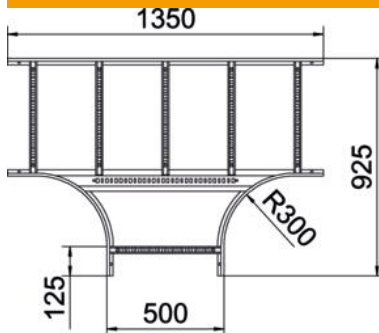

Width	500 mm
Height	60 mm
Dimension B	500 mm
Dimension R	300 mm

Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Connector version	Without connectors
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	no
Rail thickness	1.5 mm