

Technical data sheet

T piece 60 FT

Item number: 6213880



T piece, horizontal, for all cable ladder types of 60 mm side height.
Connectors should be ordered separately and in the appropriate quantity.



St	Steel
FT	Hot-dip galvanised

Master data

Item number	6213880
Type	LT 660 R5 FT
Description 1	T piece
Description 2	for cable ladder, horizontal
Manufacturer	OBO
Dimension	60x600
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	1039 kg
Weight unit	kg/100 pc.


Technical data sheet

T piece 60 FT

Item number: 6213880



Dimensions

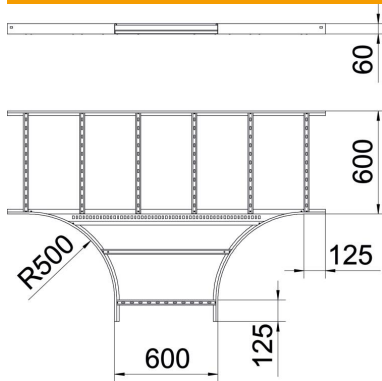

Width	600 mm
Height	60 mm
Dimension B	600 mm
Dimension R	500 mm

Technical data

Version of the rungs	Profile unperforated
Side rail version	Flat profile
Type	Exit symmetrical
Maintain electrical functions	no
Rustproof steel, pickled	no
Wide-span version	no
Rail thickness	1.5 mm