


Technical data sheet

Straight and angle connector 200 FT

Item number: 6083200

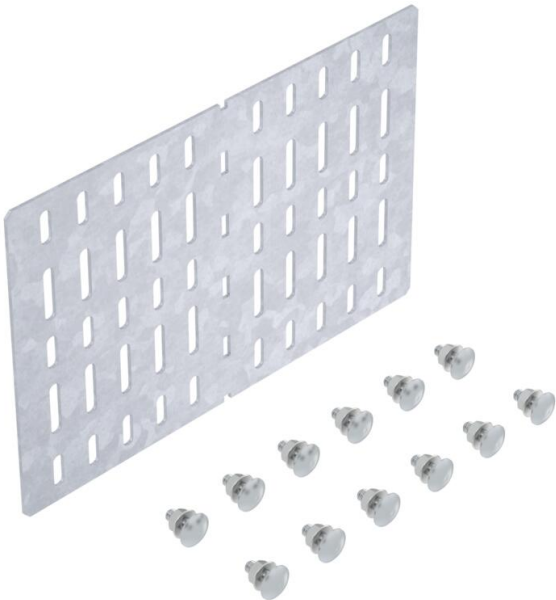

Usable as a straight connector for straight connections of cable trays (FT) with a side height of 200 mm. Usable as angle connector for horizontal brackets without fittings.



- St

Steel
- FT

Hot-dip galvanised

Master data

Item number	6083200
Description 1	Straight and angle connector
Description 2	for MFR cable tray
Manufacturer	OBO
Dimension	200x300
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	2
Unit of quantity	Piece
Weight	113.2 kg
Weight unit	kg/100 pc.


Technical data sheet

Straight and angle connector 200 FT

Item number: 6083200



Dimensions

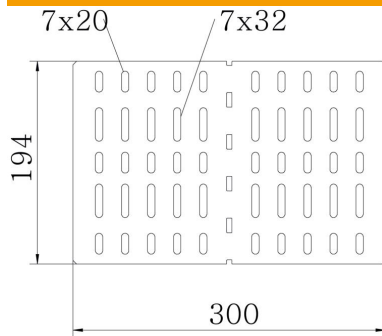

Dimension	300 x 194 x 2
Length	300 mm
Width	2.5 mm
Height	194 mm
Height	8 in
Plate thickness	2.5 mm

Technical data

Version for	Straight and angle connector
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Suitable for cable tray system height	200 mm
Adjustable connector, horizontal	no
Articulated connector, vertical	no
Rustproof steel, pickled	no
Connection type	Screw connector