

# Technical data sheet

## Mounting and fastening plate T350

Item number: 2007882



This mounting and fastening plate gives the options for variable fixing of external components in the junction box. It consists of strip-galvanised sheet steel of a material thickness of 2 mm.

The appropriate fastening holes are drilled into the steel plate for the component that needs to be fixed. Then, the products can be attached onto the sheet with cable ties, screws or similar fastening materials.

Using the screws included in the scope of the delivery, the mounting fastening plate can now be fixed in the appropriate T series (T 100) junction box.



<b>St</b>	Steel
<b>FS</b>	Strip galvanized

### Master data

Item number	2007882
Type	MBP T100
Description 1	Mounting fastening plate
Description 2	incl. fastening screws
Manufacturer	OBO
Dimension	100x75x2
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	8.5 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Mounting and fastening plate T350

Item number: 2007882



### Dimensions

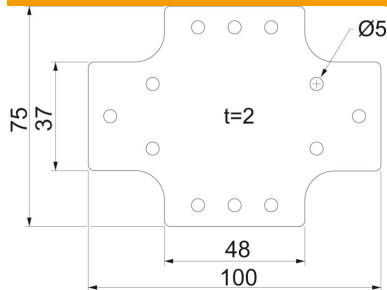

Width	100 mm
Height	75 mm
Dimension B	75 mm
Dimension B1	37 mm
Dimension L	100 mm
Dimension L1	48 mm

### Technical data

Material thickness	2 mm
With perforation	yes