

Technical data sheet

Base, MultiBase + NPE with remote signalling

Item number: 5096657




- Suitable for V 25-B+C, V 20-C and V10-C
- Pre-mounted and ready for connection
- Multifunction terminals for easy connection to series-mounted devices
- Upper parts can be rotated through 180 degrees
- With remote signalling, potential-free NO contact, for function monitoring
- 3+1 protection circuit for TN-S and TT network systems



Master data

Item number	5096657
Type	MB 2+NPE+FS
Description 1	MultiBase
Description 2	2-pole + NPE w. signal contact
Manufacturer	OBO
Dimension	2+NPE+FS
Smallest sales unit	1
Unit of quantity	Piece
Weight	21.3 kg
Weight unit	kg/100 pc.

Dimensions

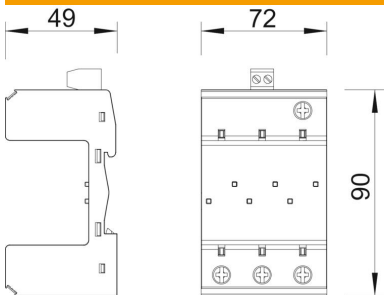

Technical data sheet

Base, MultiBase + NPE with remote signalling

Item number: 5096657



Technical data

Version for	2+NPE
Pole version	2+N/PE
Structural width in division units (division unit, 17.5 mm)	3
Operating temperature, max.	80 °C
Operating temperature, min.	-40 °C
Remote signalling	yes
Conductor cross-section, rigid (single-wire/multiwire), max.	35 mm ²
Conductor cross-section, rigid (single-wire/multiwire), min.	2.5 mm ²
Installation type	DIN rail 35 mm
Network form	Other
Protection rating	IP20