


Technical data sheet

Cable tray MFR 200 FT

Item number: 6083060

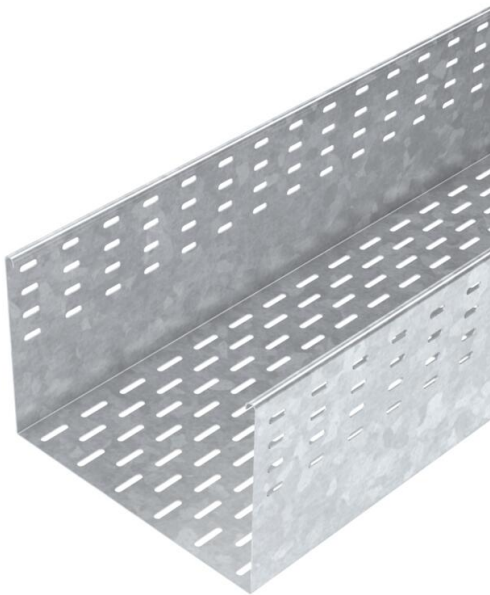

MFR = mobile radio tray
Magnetic shield insulation without cover 20 dB, with cover 50 dB.



St

Steel

FT

Hot-dip galvanised

Master data	
Item number	6083060
Type	MFR 230 FT
Description 1	Mobile radio channel
Description 2	perforated
Manufacturer	OBO
Dimension	200x300x3000
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	3
Unit of quantity	Metre
Weight	825.767 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	18,5671 kg CO2e / 1 Meter


Technical data sheet

Cable tray MFR 200 FT

Item number: 6083060



Dimensions

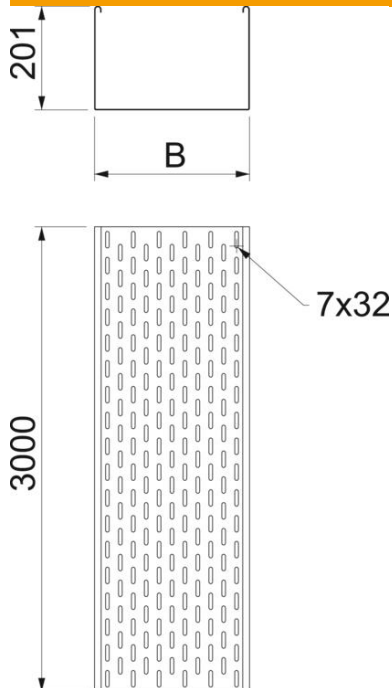

Dimension	200 x 300
Length	3,000 mm
Length	118 ft
Width	300 mm
Width	12 in
Height	200 mm
Plate thickness	0.06 in
Plate thickness	1.5 mm
Dimension B	300 mm

Technical data

Connector version	Without connectors
Mounting system fastening type	Floor Ceiling Wall
Walkable	no
Maintain electrical functions	no
With cover	no
Mounting perforation in base	yes
NATO hole pattern	no
Usable cross-section	600 cm ²
Usable cross-section	60000 mm ²
Rustproof steel, pickled	no
Side perforation	yes
Wide-span version	no
Type of connector, cable support system	Screwed