


# Technical data sheet

## Clamp connector

Item number: 6066143



Clamp connector for straight connection of cable trays, according to the marine standard, with a side height of 15 mm.

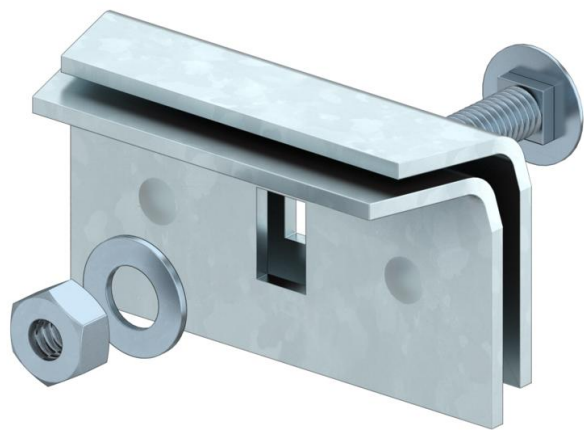

St

Steel

FT

Hot-dip galvanised

| Master data         |                                |
|---------------------|--------------------------------|
| Item number         | 6066143                        |
| Description 1       | Clamp connector                |
| Description 2       | for cable tray marine standard |
| Manufacturer        | OBO                            |
| Colour              | zinc                           |
| Material            | Steel                          |
| Surface             | Hot-dip galvanised             |
| Surface standard    | DIN EN ISO 1461                |
| Smallest sales unit | 25                             |
| Unit of quantity    | Piece                          |
| Weight              | 8.5 kg                         |
| Weight unit         | kg/100 pc.                     |


# Technical data sheet

## Clamp connector


Item number: 6066143



### Dimensions

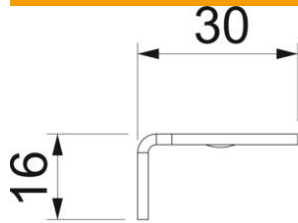

|           |              |
|-----------|--------------|
| Dimension | 9 x 23 x 100 |
| Length    | 100 mm       |
| Width     | 23 mm        |
| Height    | 9 mm         |

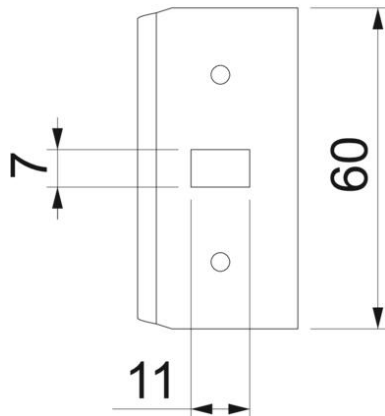

### Technical data

|                                       |                    |
|---------------------------------------|--------------------|
| Version for                           | Straight connector |
| Suitable for mesh cable tray          | no                 |
| Suitable for cable ladder             | no                 |
| Suitable for cable tray               | yes                |
| Suitable for cable tray system height | 15 mm              |
| Adjustable connector, horizontal      | no                 |
| Articulated connector, vertical       | no                 |
| Rustproof steel, pickled              | no                 |
| Connection type                       | Miscellaneous      |