

Technical data sheet


MMS-plus KS 5x50 countersunk head tie, for cable clip

Item number: 3498204



Bolt tie for direct mounting without additional anchors in concrete and masonry.
With small countersunk head to fasten cable clips through the threaded foot.

Load-bearing capacities under fire loads proven up to fire resistance class R120.

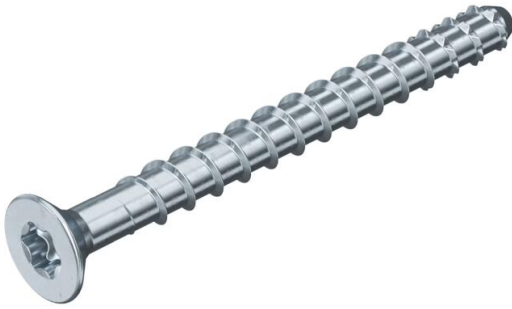

St

Steel

G

Electrogalvanized

Master data

Item number	3498204
Type	MMS+ KS 5x50
Description 1	Countersunk anchor
Description 2	for cable clip
Manufacturer	OBO
Dimension	5x50mm
Colour	zinc
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	200
Unit of quantity	Piece
Weight	0.46 kg
Weight unit	kg/100 pc.


Technical data sheet

MMS-plus KS 5x50 countersunk head tie, for cable clip


Item number: 3498204



Dimensions

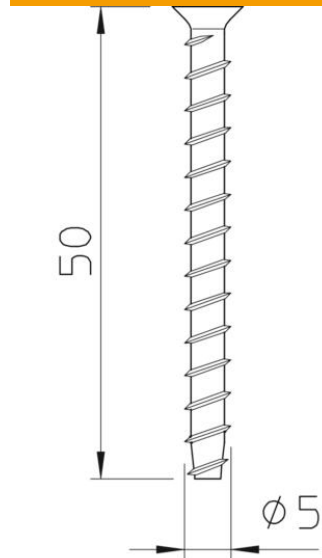

Dimension	5 x 50
Length	50 mm
Dimension L	50 mm

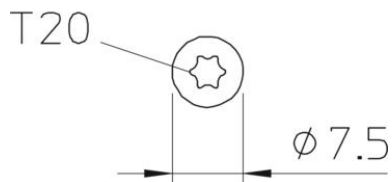

Technical data

Drill hole diameter, min.	4 mm
Thread diameter ST	5
Head diameter	7.5 mm
Head shape	Countersunk head
Screw system	Torx