

# Technical data sheet

MMS-plus SS 10x75 hexagonal tie, with pressed washer,  
made of A4 stainless steel  
Item number: 3498126



Stainless steel screw-in anchor for direct mounting without additional anchors in cracked and uncracked concrete and masonry. With hex head drive and pressed washer to accept large loads. Suitable for fastening suspended loads from suspended supports and wall brackets in wet rooms and in outdoor areas.

Construction product tested according to EAD and CE mark, with European Technical Assessment (ETA) and proof of suitability. Load-bearing capacities under fire loads proven up to fire resistance class R120.



A4 Stainless steel

## Master data


Item number	3498126
Type	MMS+ SS 10x75 A4
Description 1	Hexagon head anchor
Description 2	with combined washer
Manufacturer	OBO
Dimension	10x75mm
Colour	stainless steel
Material	Stainless steel
Smallest sales unit	25
Unit of quantity	Piece
Weight	3.7 kg
Weight unit	kg/100 pc.

# Technical data sheet

MMS-plus SS 10x75 hexagonal tie, with pressed washer,  
made of A4 stainless steel  
Item number: 3498126



## Dimensions

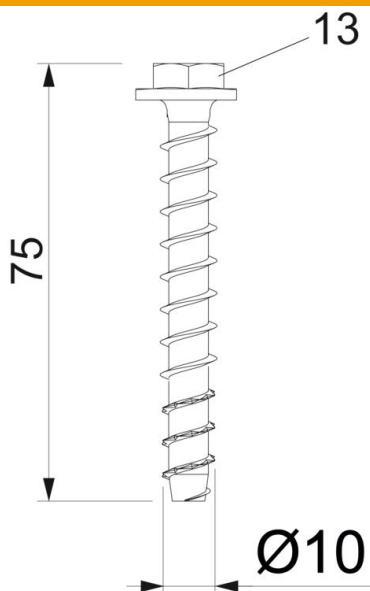

Dimension	10x75
Length	75 mm
Dimension L	75 mm

## Technical data

Anchor/nail/bolt version	Spiral anchor
Drill hole diameter, min.	8 mm
Thread	10
Head diameter	19 mm
Head shape	Hexagonal
WAF	13
Screw system	Hexagonal