


Technical data sheet

MMS-plus SS 10x80 hexagonal tie, with pressed washer

Item number: 3498124

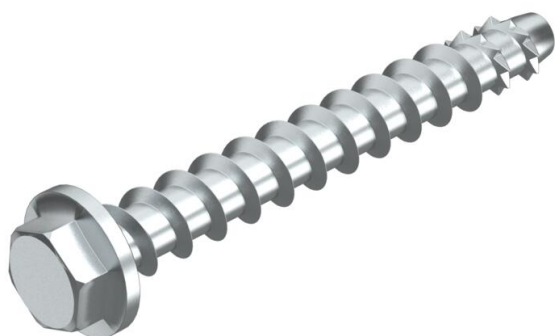

Bolt tie for direct mounting without additional anchors in cracked and uncracked concrete and masonry. With hex head drive and pressed washer to accept large loads. Suitable for fastening suspended loads from suspended supports and wall brackets.

Construction product tested according to EAD and CE mark, with European Technical Assessment (ETA) and proof of suitability. Load-bearing capacities under fire loads proven up to fire resistance class R120.



St Steel

G Electrogalvanized

Master data

| | |
|---------------------|----------------------------|
| Item number | 3498124 |
| Type | MMS+ SS 10x80 |
| Description 1 | Hexagon head anchor |
| Description 2 | with combined washer |
| Manufacturer | OBO |
| Dimension | 10x80mm |
| Colour | zinc |
| Material | Steel |
| Surface | Electrogalvanized |
| Surface standard | EN ISO 19598 / EN ISO 4042 |
| Smallest sales unit | 25 |
| Unit of quantity | Piece |
| Weight | 4 kg |
| Weight unit | kg/100 pc. |


Technical data sheet

MMS-plus SS 10x80 hexagonal tie, with pressed washer

Item number: 3498124



Dimensions

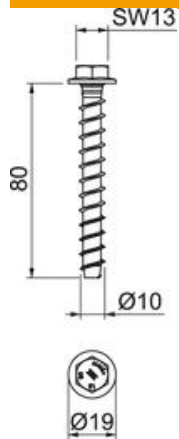

| | |
|-------------|---------|
| Dimension | 10 x 80 |
| Length | 80 mm |
| Dimension L | 80 mm |

Technical data

| | |
|---------------------------|---------------|
| Anchor/nail/bolt version | Spiral anchor |
| Drill hole diameter, min. | 8 mm |
| Thread | 10 |
| Thread diameter ST | 10 |
| Head diameter | 19 mm |
| Head shape | Hexagonal |
| WAF | 13 |
| Screw system | Hexagonal |