

Technical data sheet

MMS-plus SS 10x95 hexagonal tie, with pressed washer,
made of A4 stainless steel
Item number: 3498128



Stainless steel screw-in anchor for direct mounting without additional anchors in cracked and uncracked concrete and masonry. With hex head drive and pressed washer to accept large loads. Suitable for fastening suspended loads from suspended supports and wall brackets in wet rooms and in outdoor areas.

Construction product tested according to EAD and CE mark, with European Technical Assessment (ETA) and proof of suitability. Load-bearing capacities under fire loads proven up to fire resistance class R120.



A4 Stainless steel

Master data


| | |
|---------------------|----------------------|
| Item number | 3498128 |
| Type | MMS+ SS 10x95 A4 |
| Description 1 | Hexagon head anchor |
| Description 2 | with combined washer |
| Manufacturer | OBO |
| Dimension | 10x95mm |
| Colour | stainless steel |
| Material | Stainless steel |
| Smallest sales unit | 25 |
| Unit of quantity | Piece |
| Weight | 4.6 kg |
| Weight unit | kg/100 pc. |

Technical data sheet

MMS-plus SS 10x95 hexagonal tie, with pressed washer,
made of A4 stainless steel
Item number: 3498128



Dimensions

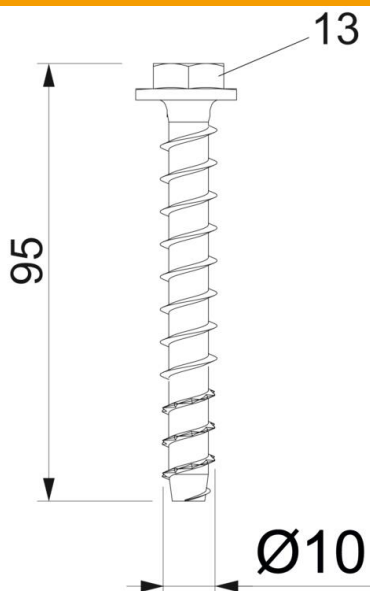

| | |
|-------------|-------|
| Dimension | 10x95 |
| Length | 95 mm |
| Dimension L | 95 mm |

Technical data

| | |
|---------------------------|---------------|
| Anchor/nail/bolt version | Spiral anchor |
| Drill hole diameter, min. | 8 mm |
| Thread | 10 |
| Head diameter | 19 mm |
| Head shape | Hexagonal |
| WAF | 13 |
| Screw system | Hexagonal |