


Technical data sheet

Mounting plate 2 x data socket type A for System 55

Item number: 7408701

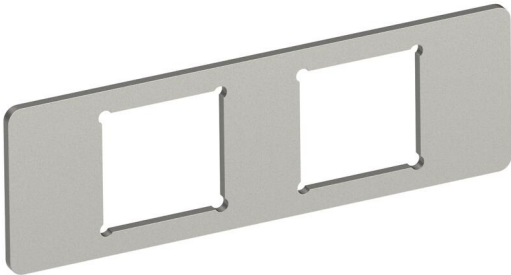

Mounting plate to accept two connection sockets for data technology of the following types: AMP TYCO: Standard 110Connect, SL Series 110Connect and Tool-less, AMP-Twist; Brand-Rex: unshielded module; GG45; TKM RJ MOD; Nexans: LANmark module with Adapter-Clip; Siemon CAT6; 3M K6 and K10.

Dimensions of a mounting opening in mm: 20.10 x 14.80.



A2 Stainless steel

Master data		
Item number	7408701	
Type	MPMT45 2A	
Description 1	Mounting plate	
Description 2	with 2x hole pattern Type A	
Manufacturer	OBO	
Dimension	77x24x1,5	
Material	Stainless steel	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	1.43 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,1733 kg CO2e / 1 Piece	

Dimensions	

Technical data sheet

Mounting plate 2 x data socket type A for System 55

Item number: 7408701



Technical data

Connection options	2 connection sockets for data technology of the following types: AMP TYCO: Standard 110Connect, SL Series 110Connect and Toolless, AMP-Twist; Brand-Rex: unshielded module; GG45; TKM RJ MOD; Nexans: LANmark module with Adapter-Clip; Siemon CAT6; 3M K6 and
Fastening type	Lockable
Labelling panel	no
Floor covering protection frame	no
Floor plate	no
Lowerable to be flush-floor	no
Seal installation option	no
Installation opening for on-floor tank	no
Decouplable	no
Suitable for raised floor installation	yes
Suitable for screed-flush closed underfloor ducts	yes
Suitable for screed-covered underfloor ducts	yes
Suitable for cavity floor installation	yes
Suitable for underfloor ducts	yes
With floor covering recess	no
Heavy-duty version	no
Strain relief option	yes