

# Technical data sheet

## MS4022 mounting rail, heavy-duty, slot 18 mm, FT

Item number: 6007244



MS4022 profile rail for use as rung in heavy-duty ladders.  
Maximum rung load 175 kg.  
The appropriate clamp clip is type 2056U.



|    |                    |
|----|--------------------|
| St | Steel              |
| FT | Hot-dip galvanised |

### Master data

|                     |                    |
|---------------------|--------------------|
| Item number         | 6007244            |
| Description 1       | Profile rail       |
| Description 2       | for U-support      |
| Manufacturer        | OBO                |
| Dimension           | 492x40x22,5        |
| Material            | Steel              |
| Surface             | Hot-dip galvanised |
| Surface standard    | DIN EN ISO 1461    |
| Smallest sales unit | 1                  |
| Unit of quantity    | Piece              |
| Weight              | 81.5 kg            |
| Weight unit         | kg/100 pc.         |


# Technical data sheet

MS4022 mounting rail, heavy-duty, slot 18 mm, FT


Item number: 6007244



## Dimensions

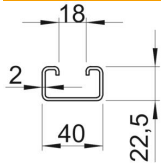

|                   |            |
|-------------------|------------|
| lampDimension WxH | 40x22,5 mm |
| Length            | 492 mm     |
| Width             | 40 mm      |
| Height            | 22.5 mm    |

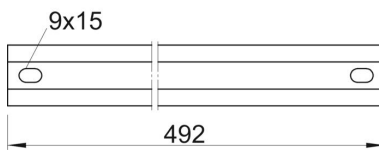

## Technical data

|                     |                 |
|---------------------|-----------------|
| Type of perforation | Perforated back |
| Version for         | Single profile  |
| Material thickness  | 2 mm            |
| Profile shape       | C profile       |
| Slot width          | 18 mm           |