

Technical data sheet

Mounting rail MS4022, heavy-duty, slot 18 mm, A4, perforated

Item number: 1121963



Heavy-duty C profile rail for individual installation of support constructions, e.g. for cable trays or as a panel for switchgear cabinets. Can also be used for cable routing, in conjunction with clamp clips with a U foot.



- A4 Stainless steel
- 2B Bright, treated

Master data		
Item number	1121963	
Type	MS4022P2000A4	
Description 1	Profile rail	
Description 2	perforated, slot 18mm	
Manufacturer	OBO	
Dimension	2000x40x22,5	
Material	Stainless steel	
Surface	Bright, treated	
Surface standard		
Smallest sales unit	2	
Unit of quantity	Metre	
Weight	147.6 kg	
Weight unit	kg/100 m	
CO Footprint (GWP) Cradle-to-Gate	0,0204 kg COe / 1 Meter	


Technical data sheet

Mounting rail MS4022, heavy-duty, slot 18 mm, A4, perforated

Item number: 1121963



Dimensions

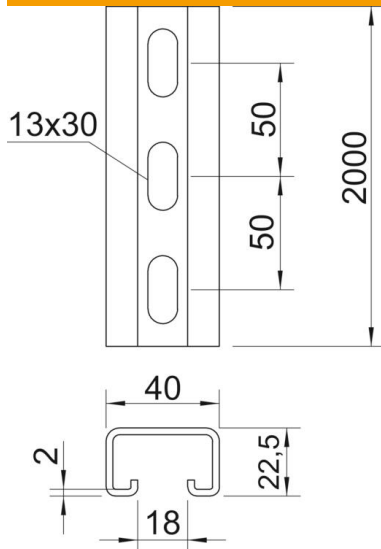

Length	2,000 mm
Width	40 mm
Height	22.5 mm
Dimension L	2,000 mm

Technical data

Type of perforation	Perforated back
Version for	Single profile
Drill hole spacing, centre	50 mm
Material thickness	2 mm
With perforation	no
With tothing	no
Profile shape	C profile
Slot width	18 mm
Static value A	1.74 cm ²
Static value I _y	1.86 cm
Static value I _z	4.46 cm
Static value W _y	1.05 cm ²
Static value W _z	2.23 cm ²