

# Technical data sheet

## MS4121 mounting rail, slot 22 mm, A2, perforated

Item number: 1122925



Heavy-duty C profile rail for individual installation of support constructions, e.g. for cable trays or as a panel for switchgear cabinets. Can also be used for cable routing, in conjunction with clamp clips with a U foot.



**A2** Stainless steel

**2B** Bright, treated

### Master data

|                                   |                         |
|-----------------------------------|-------------------------|
| Item number                       | 1122925                 |
| Type                              | MS4121P2000A2           |
| Description 1                     | Profile rail            |
| Description 2                     | perforated, slot 22mm   |
| Manufacturer                      | OBO                     |
| Dimension                         | 2000x41x21              |
| Material                          | Stainless steel         |
| Surface                           | Bright, treated         |
| Surface standard                  |                         |
| Smallest sales unit               | 2                       |
| Unit of quantity                  | Metre                   |
| Weight                            | 140.95 kg               |
| Weight unit                       | kg/100 m                |
| CO Footprint (GWP) Cradle-to-Gate | 7,3593 kg COe / 1 Meter |


# Technical data sheet

## MS4121 mounting rail, slot 22 mm, A2, perforated

Item number: 1122925



### Dimensions

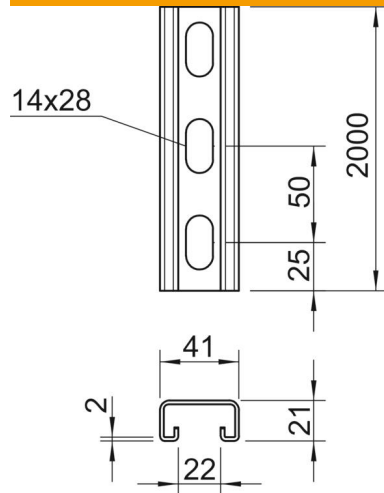

|             |          |
|-------------|----------|
| Length      | 2,000 mm |
| Width       | 41 mm    |
| Height      | 21 mm    |
| Dimension L | 2,000 mm |

### Technical data

|                               |                      |
|-------------------------------|----------------------|
| Breakable                     | no                   |
| Type of perforation           | Perforated back      |
| Version for                   | Single profile       |
| Drill hole spacing, centre    | 50 mm                |
| Maintain electrical functions | no                   |
| Material thickness            | 2 mm                 |
| With perforation              | yes                  |
| With tothing                  | yes                  |
| Profile shape                 | C profile            |
| Slot width                    | 22 mm                |
| Static value A                | 1.65 cm <sup>2</sup> |
| Static value Iy               | 0.95 cm              |
| Static value Iz               | 4.51 cm              |
| Static value Wy               | 0.89 cm <sup>2</sup> |
| Static value Wz               | 2.2 cm <sup>2</sup>  |