

Technical data sheet

MS4141 mounting rail, slot 22 mm, perforated A4

Item number: 1123033



Heavy-duty C profile rail for individual installation of support constructions, e.g. for cable trays or as a panel for switchgear cabinets. Can also be used for cable routing, in conjunction with clamp clips with a U foot.



- A4 Stainless steel
- 2B Bright, treated

Master data	
Item number	1123033
Type	MS4141P0300A4
Description 1	Profile rail
Description 2	perforated, slot 22mm
Manufacturer	OBO
Dimension	300x41x41
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	72 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	4,0157 kg COe / 1 Piece


Technical data sheet

MS4141 mounting rail, slot 22 mm, perforated A4

Item number: 1123033



Dimensions

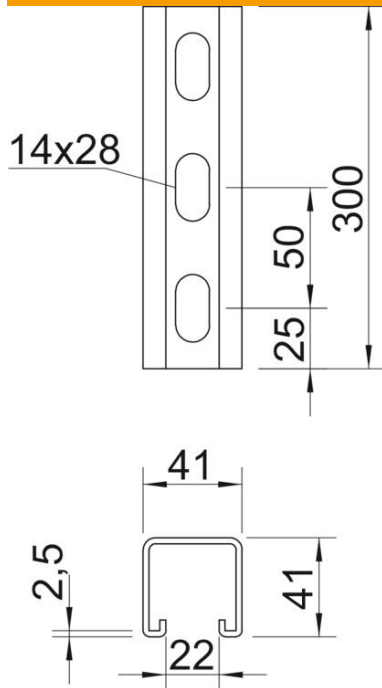

Length	300 mm
Width	41 mm
Height	41 mm
Dimension L	300 mm

Technical data

Breakable	no
Type of perforation	Perforated back
Version for	Single profile
Drill hole spacing, centre	50 mm
Maintain electrical functions	no
Hole size	14x28 mm
Material thickness	2.5 mm
With toothing	yes
Profile shape	C profile
Slot width	22 mm
Static value A	2.97 cm ²
Static value Iy	6.05 cm
Static value Iz	9.01 cm
Static value Wy	2.91 cm ²
Static value Wz	4.4 cm ²