

# Technical data sheet

## MS4141 mounting rail, slot 22 mm, perforated A4

Item number: 1123039



Heavy-duty C profile rail for individual installation of support constructions, e.g. for cable trays or as a panel for switchgear cabinets. Can also be used for cable routing, in conjunction with clamp clips with a U foot.



A4	Stainless steel
2B	Bright, treated

Master data		
Item number	1123039	
Type	MS4141P0600A4	
Description 1	Profile rail	
Description 2	perforated, slot 22mm	
Manufacturer	OBO	
Dimension	600x41x41	
Material	Stainless steel	
Surface	Bright, treated	
Surface standard		
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	147 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	8,3851 kg COe / 1 Piece	


# Technical data sheet

MS4141 mounting rail, slot 22 mm, perforated A4

Item number: 1123039



## Dimensions

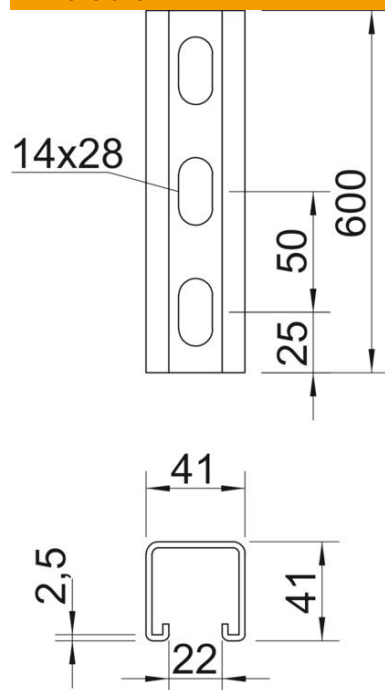

Length	600 mm
Width	41 mm
Height	41 mm
Dimension L	600 mm

## Technical data

Breakable	no
Type of perforation	Perforated back
Version for	Single profile
Drill hole spacing, centre	50 mm
Maintain electrical functions	no
Hole size	14x28 mm
Material thickness	2.5 mm
With toothing	yes
Profile shape	C profile
Slot width	22 mm
Static value A	2.97 cm <sup>2</sup>
Static value Iy	6.05 cm
Static value Iz	9.01 cm
Static value Wy	2.91 cm <sup>2</sup>
Static value Wz	4.4 cm <sup>2</sup>