

Technical data sheet

MS4141 mounting rail, slot 22 mm, perforated FS (FT/A4)

Item number: 1122910



Heavy-duty C profile rail for individual installation of support constructions, e.g. for cable trays or as a panel for switchgear cabinets. Can also be used for cable routing, in conjunction with clamp clips with a U foot.



- St Steel
- FS Strip galvanized

Master data		
Item number	1122910	
Type	MS4141P3000FS	
Description 1	Profile rail	
Description 2	perforated, slot 22mm	
Manufacturer	OBO	
Dimension	3000x41x41	
Material	Steel	
Surface	Strip galvanized	
Surface standard	DIN EN 10346	
Smallest sales unit	3	
Unit of quantity	Metre	
Weight	247.5 kg	
Weight unit	kg/100 m	
CO Footprint (GWP) Cradle-to-Gate	5,8908 kg COe / 1 Meter	


Technical data sheet

MS4141 mounting rail, slot 22 mm, perforated FS (FT/A4)

Item number: 1122910



Dimensions

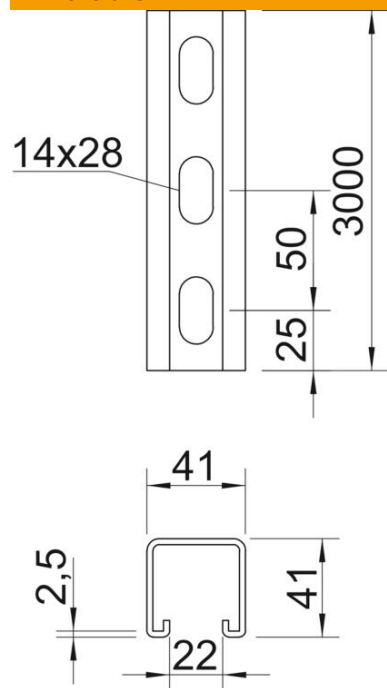

Length	3,000 mm
Width	41 mm
Height	41 mm
Dimension L	3,000 mm

Technical data

Breakable	no
Type of perforation	Perforated back
Version for	Single profile
Drill hole spacing, centre	50 mm
Maintain electrical functions	yes
Hole size	14x28 mm
Material thickness	2.5 mm
With perforation	yes
With toothing	yes
Profile shape	C profile
Slot width	22 mm
Static value A	2.97 cm ²
Static value Iy	6.05 cm
Static value Iz	9.01 cm
Static value Wy	2.91 cm ²
Static value Wz	4.4 cm ²