

Technical data sheet

MS4182 mounting rail, slot 22 mm, double, FS, perforated

Item number: 1122676



Heavy-duty profile/mounting rail with continuous perforation in base, slot width 22 mm. Double version, i.e. two profile rails are interconnected on the base (clinched).



St	Steel
FS	Strip galvanized

Master data

Item number	1122676
Type	MS4182P3000FS
Description 1	Profile rail
Description 2	perforated, slot 22mm
Manufacturer	OBO
Dimension	3000x41x82
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	3
Unit of quantity	Metre
Weight	402.2 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	9,7144 kg COe / 1 Meter


Technical data sheet

MS4182 mounting rail, slot 22 mm, double, FS, perforated

Item number: 1122676



Dimensions

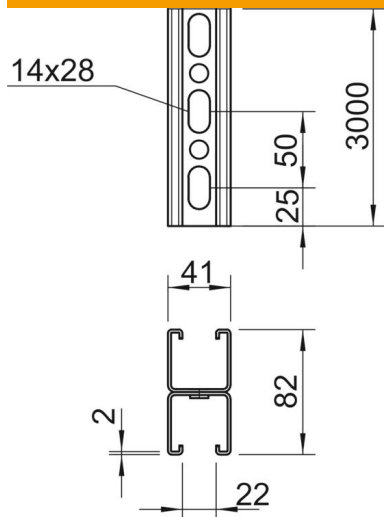

Length	3,000 mm
Width	41 mm
Height	82 mm
Dimension L	3,000 mm

Technical data

Breakable	no
Type of perforation	Perforated bar
Version for	Double profile
Maintain electrical functions	no
Hole size	14x28 mm
Material thickness	2 mm
With tothing	yes
Profile shape	C profile
Slot width	22 mm
Static value A	4.86 cm ²
Static value Iy	30.69 cm
Static value Iz	15.11 cm
Static value Wy	2.51 cm ²
Static value Wz	2.69 cm ²