


# Technical data sheet

## Hammer-head bolt A4

Item number: 1148414



Hammer-head bolt for use with MS4121 and MS4141 profile rails

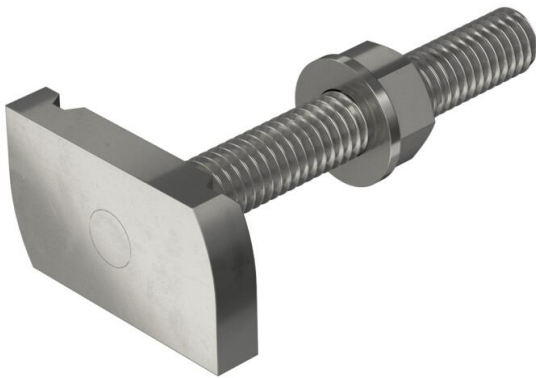

**A4** Stainless steel

**2B** Bright, treated

### Master data

|                                   |                              |
|-----------------------------------|------------------------------|
| Item number                       | 1148414                      |
| Type                              | MS41HB M8x60 A4              |
| Description 1                     | Hammerhead screw             |
| Description 2                     | for profile rail MS4121/4141 |
| Manufacturer                      | OBO                          |
| Dimension                         | M8x60mm                      |
| Material                          | Stainless steel              |
| Surface                           | Bright, treated              |
| Surface standard                  |                              |
| Smallest sales unit               | 25                           |
| Unit of quantity                  | Piece                        |
| Weight                            | 6 kg                         |
| Weight unit                       | kg/100 pc.                   |
| CO Footprint (GWP) Cradle-to-Gate | 0,2874 kg COe / 1 Piece      |



# Technical data sheet

## Hammer-head bolt A4

Item number: 1148414



### Dimensions

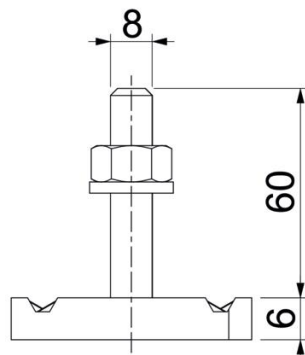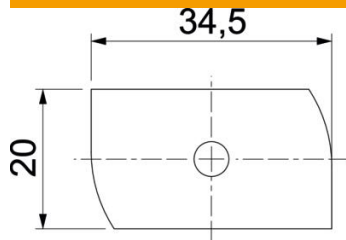

|             |         |
|-------------|---------|
| Length      | 34.5 mm |
| Width       | 20 mm   |
| Height      | 6 mm    |
| Dimension H | 6 mm    |
| Dimension L | 60 mm   |

### Technical data

|                            |          |
|----------------------------|----------|
| Torque                     | 6.2 Nm   |
| Suitable for mounting rail | yes      |
| Thread                     | M 8 x 60 |
| Washer Ø                   | 16 mm    |