

 
Technical data sheet

MS5030 mounting rail, slot 22 mm, A2, perforated

Item number: 1121499



Heavy-duty C profile rail for individual installation of support constructions, e.g. for cable trays or as a panel for switchgear cabinets. Can also be used for cable routing, in conjunction with clamp clips with a U foot.



A2 Stainless steel

2B Bright, treated

Master data

| | |
|-----------------------------------|--------------------------|
| Item number | 1121499 |
| Type | MS5030P6000A2 |
| Description 1 | Profile rail |
| Description 2 | perforated, slot 22mm |
| Manufacturer | OBO |
| Dimension | 6000x50x30 |
| Material | Stainless steel |
| Surface | Bright, treated |
| Surface standard | |
| Smallest sales unit | 6 |
| Unit of quantity | Metre |
| Weight | 282.5 kg |
| Weight unit | kg/100 m |
| CO Footprint (GWP) Cradle-to-Gate | 14,4447 kg COe / 1 Meter |


Technical data sheet

MS5030 mounting rail, slot 22 mm, A2, perforated

Item number: 1121499



Dimensions

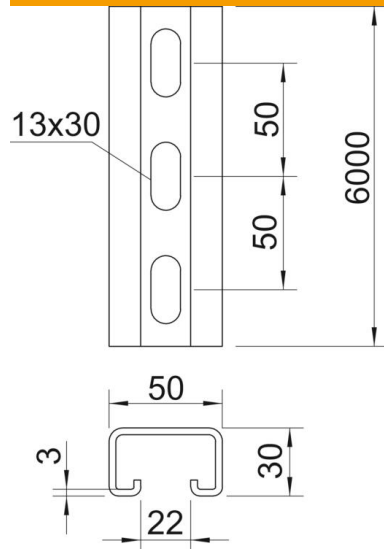

| | |
|-------------|----------|
| Length | 6,000 mm |
| Width | 50 mm |
| Height | 30 mm |
| Dimension L | 6,000 mm |

Technical data

| | |
|-------------------------------|----------------------|
| Breakable | no |
| Type of perforation | Perforated back |
| Version for | Single profile |
| Drill hole spacing, centre | 50 mm |
| Maintain electrical functions | no |
| Material thickness | 3 mm |
| With perforation | yes |
| With toothing | no |
| Profile shape | C profile |
| Slot width | 18 mm |
| Static value A | 3.39 cm ² |
| Static value I _y | 3.99 cm |
| Static value I _z | 13.11 cm |
| Static value W _y | 3.95 cm ² |
| Static value W _z | 6.38 cm ² |