

# Technical data sheet

## MS4141 mounting rail, slot 22 mm, A2, perforated

Item number: 1122978



Heavy-duty C profile rail for individual installation of support constructions, e.g. for cable trays or as a panel for switchgear cabinets. Can also be used for cable routing, in conjunction with clamp clips with a U foot.



A2	Stainless steel
2B	Bright, treated

### Master data

Item number	1122978
Type	MSL4141P1000A2
Description 1	Profile rail
Description 2	perforated, slot 22mm
Manufacturer	OBO
Dimension	1000x41x41
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Metre
Weight	201.1 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	10,1491 kg COe / 1 Meter


# Technical data sheet

MS4141 mounting rail, slot 22 mm, A2, perforated

Item number: 1122978



## Dimensions

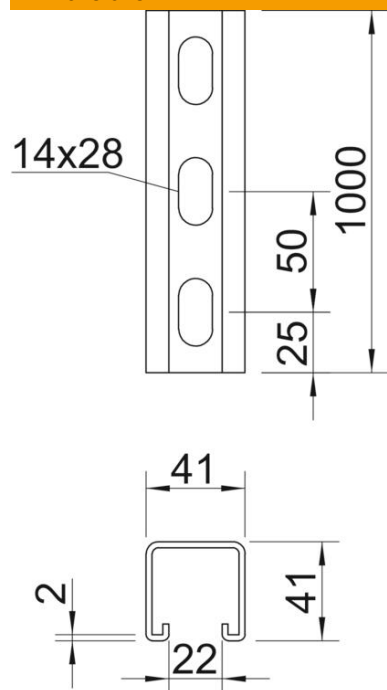

Length	1,000 mm
Width	41 mm
Height	41 mm
Dimension L	1,000 mm

## Technical data

Breakable	no
Type of perforation	Perforated back
Version for	Single profile
Drill hole spacing, centre	50 mm
Maintain electrical functions	no
Hole size	14x28 mm
Material thickness	2 mm
With perforation	yes
With toothing	yes
Profile shape	C profile
Slot width	22 mm
Static value A	2.45 cm <sup>2</sup>
Static value I <sub>y</sub>	5.18 cm
Static value I <sub>z</sub>	7.56 cm
Static value W <sub>y</sub>	2.51 cm <sup>2</sup>
Static value W <sub>z</sub>	2.69 cm <sup>2</sup>