

Technical data sheet

MS4141 mounting rail, slot 22 mm, A2, perforated

Item number: 1122980



Heavy-duty C profile rail for individual installation of support constructions, e.g. for cable trays or as a panel for switchgear cabinets. Can also be used for cable routing, in conjunction with clamp clips with a U foot.



A2	Stainless steel
2B	Bright, treated

Master data

Item number	1122980
Type	MSL4141P3000A2
Description 1	Profile rail
Description 2	perforated, slot 22mm
Manufacturer	OBO
Dimension	3000x41x41
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	3
Unit of quantity	Metre
Weight	201.1 kg
Weight unit	kg/100 m
CO Footprint (GWP) Cradle-to-Gate	10,1756 kg COe / 1 Meter



Technical data sheet

MS4141 mounting rail, slot 22 mm, A2, perforated

Item number: 1122980



Dimensions

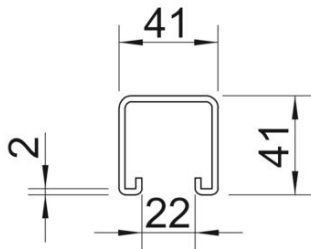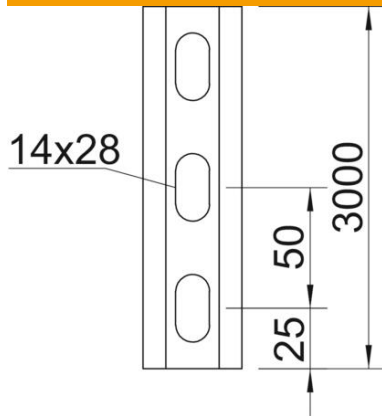

Length	3,000 mm
Width	41 mm
Height	41 mm
Dimension L	3,000 mm

Technical data

Breakable	no
Type of perforation	Perforated back
Version for	Single profile
Drill hole spacing, centre	50 mm
Maintain electrical functions	no
Hole size	14x28 mm
Material thickness	2 mm
With perforation	yes
With toothing	yes
Profile shape	C profile
Slot width	22 mm
Static value A	2.45 cm ²
Static value I _y	5.18 cm
Static value I _z	7.56 cm
Static value W _y	2.51 cm ²
Static value W _z	2.69 cm ²