

Technical data sheet

MSL4141 mounting rail, slot 22 mm, FS, perforated

Item number: 1122972



Heavy-duty C profile rail for individual installation of support constructions, e.g. for cable trays or as a panel for switchgear cabinets. Can also be used for cable routing, in conjunction with clamp clips with a U foot.



- St Steel
- FS Strip galvanized

| Master data | | |
|-----------------------------------|-------------------------|--|
| Item number | 1122972 | |
| Type | MSL4141P3000FS | |
| Description 1 | Profile rail | |
| Description 2 | perforated, slot 22mm | |
| Manufacturer | OBO | |
| Dimension | 3000x41x41 | |
| Material | Steel | |
| Surface | Strip galvanized | |
| Surface standard | DIN EN 10346 | |
| Smallest sales unit | 3 | |
| Unit of quantity | Metre | |
| Weight | 201.1 kg | |
| Weight unit | kg/100 m | |
| CO Footprint (GWP) Cradle-to-Gate | 4,7674 kg COe / 1 Meter | |



Technical data sheet

MSL4141 mounting rail, slot 22 mm, FS, perforated

Item number: 1122972



Dimensions

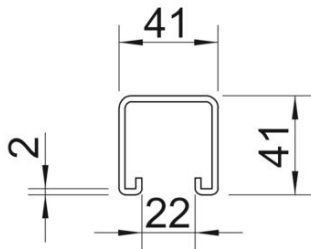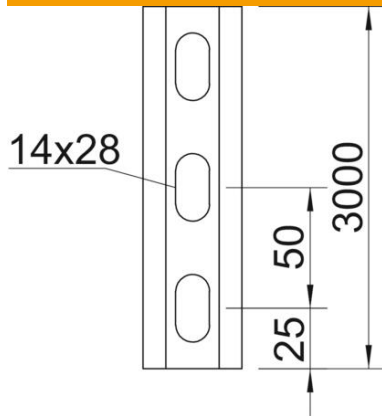

| | |
|-------------|----------|
| Length | 3,000 mm |
| Width | 41 mm |
| Height | 41 mm |
| Dimension L | 3,000 mm |

Technical data

| | |
|-------------------------------|----------------------|
| Breakable | no |
| Type of perforation | Perforated back |
| Version for | Single profile |
| Drill hole spacing, centre | 50 mm |
| Maintain electrical functions | yes |
| Hole size | 14x28 mm |
| Material thickness | 2 mm |
| With perforation | yes |
| With toothing | yes |
| Profile shape | C profile |
| Slot width | 22 mm |
| Static value A | 2.45 cm ² |
| Static value I _y | 5.18 cm |
| Static value I _z | 7.56 cm |
| Static value W _y | 2.51 cm ² |
| Static value W _z | 2.69 cm ² |