

Technical data sheet

Mini jack connection, 1 module, straight outlet, as soldered connection

Item number: 6104949



Multimedia support with one mini jack connection socket, straight cable outlet, with labelling panel, mini cinch socket (TRS 3.5 mm) with soldered connection. Support plate with locking fastening, suitable for horizontal and vertical installation in the system environment.

PC Polycarbonate

Master data		
Item number	6104949	
Type	MTG-MK L SWGR1	
Description 1	Multimedia support, audio jack	
Description 2	1xsocket with sold. connection	
Manufacturer	OBO	
Dimension	45x45mm	
Colour	Black-grey; RAL 7021	
Material	Polycarbonate	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	1.5 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0737 kg CO2e / 1 Piece	


Technical data sheet

Mini jack connection, 1 module, straight outlet, as soldered connection

Item number: 6104949



Dimensions

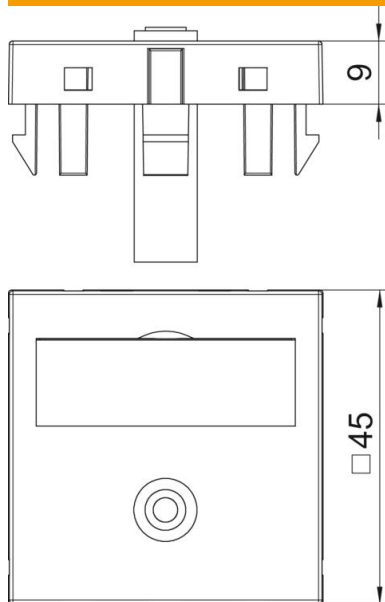

Width	45 mm
Height	45 mm

Technical data

Number of units	1
Surface version	Matt
Fastening type	Lock
Labelling panel	With labelling panel
Halogen-free	yes
Hinged cover	no
Lamp-wire connector	no
With printed label	no
With dust protection	no
Protection rating	IP20
Depth	9 mm
Support ring	no
Transparent	no
Use	Cinch
Strain relief option	no
Combination	Basic element with central cover plate
Outlet direction	Straight