


Technical data sheet

VGA connection, 1 module, straight outlet, with connection cable

Item number: 6104658



Multimedia support with one VGA connection socket, straight cable outlet, with labelling panel, short VGA connection cable (HD15), socket-socket version. Support with locking fastening, suitable for horizontal and vertical installation in the system environment.

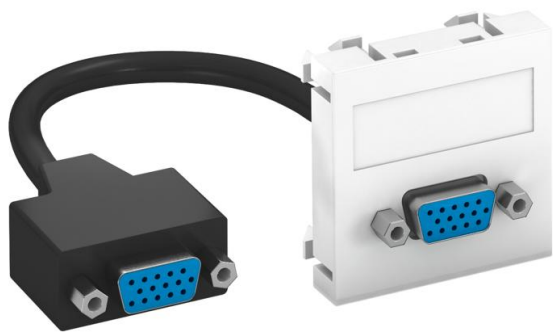

PC Polycarbonate

Master data		
Item number	6104658	
Type	MTG-VGA F RW1	
Description 1	Multimedia support, VGA	
Description 2	with cable, socket-socket	
Manufacturer	OBO	
Dimension	45x45mm	
Colour	Pure white; RAL 9010	
Material	Polycarbonate	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	5.2 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,1078 kg CO2e / 1 Piece	

Technical data sheet

VGA connection, 1 module, straight outlet, with connection cable


Item number: 6104658



Dimensions



Width	45 mm
Height	45 mm

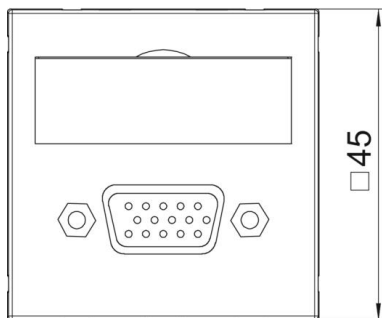

Technical data

Number of units	1
Surface version	Matt
Fastening type	Lock
Labelling panel	With labelling panel
Halogen-free	yes
Hinged cover	no
Lamp-wire connector	no
With printed label	no
With dust protection	no
Protection rating	IP20
Depth	9 mm
Support ring	no
Transparent	no
Use	VGA
Strain relief option	no
Combination	Basic element with central cover plate